


Ball valve QH-QS-6-1/8

Part number: 153487

FESTO

with QS push-in connector.
This type is suitable for vacuum.

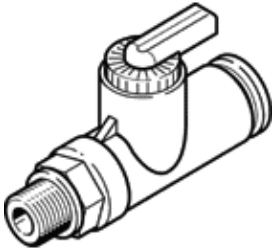

Data sheet

| Feature | Value |
|------------------------------------|---|
| Valve function | 2/2 bistable |
| Pneumatic connection, port 1 | R1/8 |
| Pneumatic connection, port 2 | QS-6 |
| Type of actuation | manual |
| Mounting type | Threaded |
| Standard nominal flow rate | 560 l/min |
| Nominal size | 2.5 mm |
| Operating pressure MPa | -0.1 ... 1 MPa |
| Working pressure | -1 ... 10 bar |
| Ambient temperature | 0 ... 60 °C |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:::] |
| Sealing principle | soft |
| Design structure | Ball valve |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Product weight | 15 g |
| Materials note | Conforms to RoHS |