

 

Pressure regulator LRMA-1/8-QS-6

Part number: 153491
Product to be discontinued

FESTO

With pressure gauge.

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

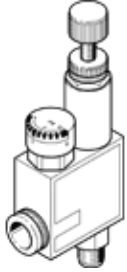

Data sheet

Feature	Value
Controller function	Output pressure constant with secondary exhaust
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	QS-6
Mounting type	with through hole
Standard nominal flow rate	75 l/min
Inlet pressure 1	0 ... 9 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Actuator lock	Knurled screw with lock nut
Assembly position	Any
Design structure	directly-controlled piston regulator with looped-through compressed air supply
Pressure gauge	with pressure gauge
Pressure regulation range	1 ... 8 bar
Product weight	54.5 g
Material of threaded plug	Brass Nickel plated
Material of threaded seal	PTFE