

 

# Pressure regulator

## LR-1/4-QS-6

Part number: 153537  
 Product to be discontinued

FESTO

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

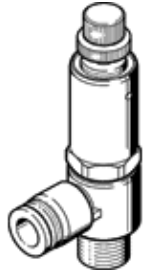

### Data sheet

Feature	Value
Controller function	Output pressure constant with secondary exhaust
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	QS-6
Mounting type	Threaded
Standard nominal flow rate	98 l/min
Inlet pressure 1	0 ... 9 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Actuator lock	Knurled screw with lock nut
Assembly position	Any
Design structure	directly-controlled piston regulator with looped-through compressed air supply
Pressure regulation range	1 ... 8 bar
Product weight	59 g
Material of threaded plug	Brass Nickel plated
Material of threaded seal	PTFE