


Swivel flange SNGB-250

Part number: 157512

FESTO

Suitable clevis foot LN, LSN.

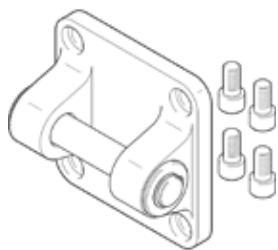

Data sheet

| Feature | Value |
|---|---|
| Size | 250 |
| Based on the standard | ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| Ambient temperature | -40 ... 90 °C |
| Product weight | 16,141 g |
| Materials note | Conforms to RoHS |
| Material mounting | Nodular graphite cast iron |
| Material mounting pin | Steel Galvanized |
| Material bearing | Plastic |
| Material disc | steel, galvanized |
| Material screws | Steel Galvanized |
| Material lock | Spring steel, galvanized |