


Resetting module PZVT-AUT

Part number: 158496

FESTO

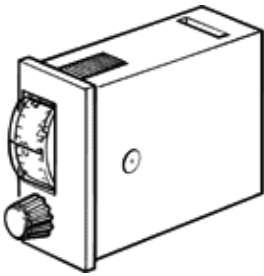

Data sheet

| Feature | Value |
|------------------------------------|---|
| Design structure | mechanical sequence counter with pneumatic actuator |
| Switch-off pressure | ≤ 0.1 bar |
| Working pressure | 2 ... 6 bar |
| Switch-on pressure | ≥ 1.6 bar |
| Standard nominal flow rate | 50 l/min |
| Adjustable delay times | 0.2 ... 2 s |
| Pause period for reset | ≥ 200 ms |
| Repetition accuracy, time setting | $\pm 0,3$ s |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:4:4] |
| Note on operating and pilot medium | Lubricated operation not possible |
| PWIS conformity | VDMA24364-B1/B2-L |
| Protection class | IP54 With protective cover and panel frame to IEC 60529 |
| Ambient temperature | -15 ... 60 °C |
| Product weight | 50 g |
| Mounting type | Front panel installation |
| Pneumatic connection | Female thread M5 |
| Materials note | Conforms to RoHS |
| Material housing | ABS |