


# Vacuum filter

## VAF-PK-4

Part number: 15889

FESTO

In-line design.

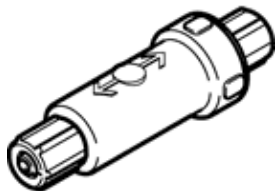

## Data sheet

Feature	Value
Nominal size	3 mm
Assembly position	Any
Grade of filtration	50 µm
Working pressure	-0.95 ... 0 bar
Note on working pressure	Only for application in open vacuum systems
Flow rate at negative pressure of -0.075 MPa (-0.75 bar, -10.875 psi)	70 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	0 ... 40 °C
Product weight	6 g
Mounting type	Line installation
Pneumatic connection	PK-4 with sleeve nut
Material of union nut	POM
Materials note	Conforms to RoHS
Material filter	Mesh PA
Material housing	PA
Ejector pulse suitability	≤ 8 bar