


T click connector NPKA-T-Q6-E-P10

Part number: 1590710

FESTO

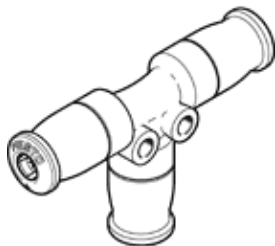

Data sheet

Feature	Value
Size	Standard
Nominal size	4 mm
Tubing insertion depth	25.8 mm
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure MPa	-0.095 ... 1 MPa
Working pressure	-0.95 ... 10 bar
Operating pressure	-13.775 ... 145 psi
Note on working pressure	Water: max. 0.6 MPa at 0 - 50 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water (liquid, free of ice)
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B2-L
Food-safe	See Supplementary material information
Ambient temperature	-10 ... 60 °C
Product weight	12.5 g
Pneumatic connection, port 1	For tubing outside diameter 6 mm
Pneumatic connection, port 2	For tubing outside diameter 6 mm
Materials note	Conforms to RoHS
Material housing	PA66-GF30
Material of threaded seal	NBR
Material sleeve	POM
Material of tubing seal	NBR