 



# Branching module PMBL-186-HP3-H

Part number: 1609073

FESTO

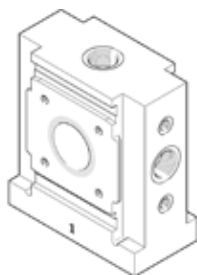

## Data sheet

Feature	Value
Nominal diameter DN	54
Series	L
Assembly position	Any
Design structure	Branching module
Operating pressure MPa	0 ... 5 MPa
Working pressure	0 ... 50 bar
CE symbol (see declaration of conformity)	according to EU printing device guideline
UKCA marking (see declaration of conformity)	UK regulation for pressure equipment
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:~:]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364 zone III
Storage temperature	-10 ... 60 °C
Food-safe	See Supplementary material information
Medium temperature	5 ... 60 °C
Ambient temperature	5 ... 60 °C
Pneumatic connection, port 3	G1
Pneumatic connection, port 4	G1
Materials note	Conforms to RoHS
Material seals	NBR
Material housing	Wrought Aluminum alloy