


# Angled plug socket MPPE-3-B

Part number: 161839

FESTO

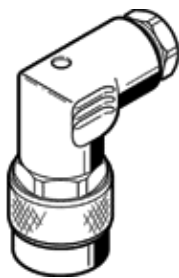

## Data sheet

Feature	Value
Connection frequency	500
Mounting type	With sleeve nut
Assembly position	Any
Product weight	65 g
Electrical connection	8-pin Plug socket angled Solderable
Operating voltage range DC	$\leq 60$ V
Permissible current load	5 A
Cable gland connection	Pg9
Permissible cable diameter	6 ... 8 mm
Terminal cross-section	0.75 mm <sup>2</sup>
Protection class	IP67
Ambient temperature	-30 ... 95 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PA
Housing color	Black
Material of union nut	PA
Material electrical contact	Copper Galvanized