

Pressure regulator

LR-1/8-D-7-O-MINI-NPT


Part number: 173647

Classic - do not use for new projects

Without threaded connection plate, connector thread in housing,
without pressure gauge

Modern alternatives can be found by entering the first four characters
of the type code in the search field.

FESTO

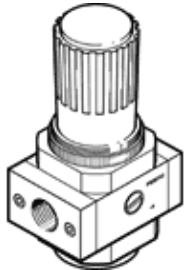

Data sheet

Feature	Value
Size	Mini
Series	D
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Air purity class at output	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Pneumatic connection, port 1	1/8 NPT
Pneumatic connection, port 2	1/8 NPT
Materials note	Conforms to RoHS