


Coupling EAMC-40-66-XX-15

Part number: 176036

FESTO

For DGE.

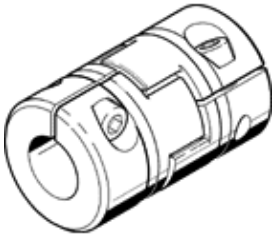

Data sheet

Feature	Value
Holder diameter 2	15 mm
Size	40
Nominal length	66 mm
Assembly position	Any
Max. speed	6,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	42.3 kgmm ²
Product weight	139 g
Materials note	Conforms to RoHS