


# Multi-pin distributor MPV-E/A08-M8

Part number: 177669

FESTO

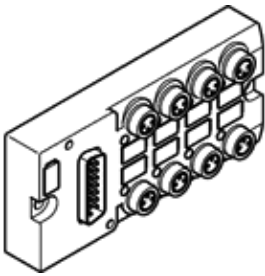

## Data sheet

Feature	Value
Mounting type	with through hole with top-hat rail Optional
Product weight	100 g
Electrical connector technology, I/O	M8 3-pin
Operating voltage range DC	10 ... 30 V
Current-carrying capacity per slot	1 A
Permissible current load	4 A
Protection class	IP65 in assembled condition to IEC 60529
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PA6 reinforced
Material socket	Brass