


# Connecting cable KMYZ-2-24-M8-0,5-LED

Part number: 177676

FESTO

for vacuum generators VAD-MYB, VADM, VADMI and multi-pin distributor MPV.

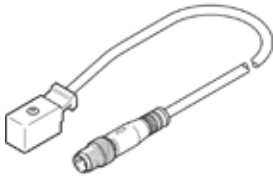

## Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with self-tapping screw
Assembly position	Any
Product weight	18 g
Electrical connection	2-pin / 3-pin angled socket / straight plug square design / M8x1
Nominal operating voltage DC	24 V
Acceptable current load at 40°C	1 A
Protective earth connection	Not available
Cable length	0.5 m
Cable attribute	Standard
Cable diameter	3.4 mm
Cable structure	2x0,25
Protection class	IP65
Ambient temperature	-10 ... 50 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Material housing	PA
Material seals	TPE-O
Material electrical contact	Bronze
Material threaded sleeve	Nickel-plated brass