


# Coupling

## EAMD-42-40-20-16X25-U

Part number: 1781043

FESTO

drive component, which transmits the rotary motion of a stepper or servo motor

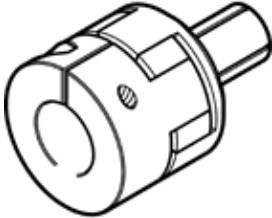

### Data sheet

Feature	Value
Holder diameter 1	20 mm
Holder diameter 2	16 mm
Size	42
Nominal length	40 mm
Assembly position	Any
Max. speed	6,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	39 kgmm <sup>2</sup>
Transferable torque	21 Nm
Product weight	189 g
Materials note	Conforms to RoHS