


# Mains outlet socket NTSD-GD-13,5

Part number: 18526

FESTO

For valve manifolds.

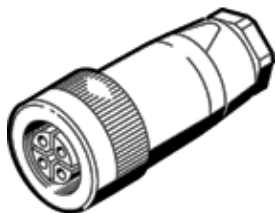

## Data sheet

Feature	Value
Mounting type	With sleeve nut
Assembly position	Any
Product weight	31 g
Electrical connection	4-pin Plug socket, straight Screwed terminal
Operating voltage range AC	$\leq 250$ V
Permissible current load	16 A
Cable gland connection	Pg13
Permissible cable diameter	6 ... 8 mm
Terminal cross-section	2.5 mm <sup>2</sup>
Protection class	IP67
Ambient temperature	-5 ... 50 °C
Storage temperature	-20 ... 70 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PBT
Material electrical contact	Copper alloy Brass