 



Pressure regulator LR-10-32-UNF-QS-1/4-U

Part number: 190926
Product to be discontinued

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

FESTO

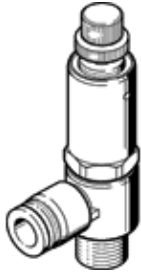

Data sheet

Feature	Value
Controller function	Output pressure constant
Pneumatic connection, port 1	10-32 UNF-2A
Pneumatic connection, port 2	QS-1/4
Mounting type	Threaded
Inlet pressure 1	0 ... 10 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Assembly position	Any
Product weight	17 g
Material of threaded plug	Brass