


# Vacuum suction cup

## ESV-50-BU

Part number: 191064

FESTO

Wearing part, easily replaceable

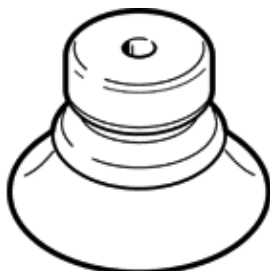

## Data sheet

Feature	Value
Suction cup height compensator	11 mm
Min. workpiece radius	150 mm
suction cup diameter	50 mm
suction cup volume	14.23 cm <sup>3</sup>
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, bellows 1.5 conv
Operating pressure MPa	-95 ... 0 kPa
Working pressure	-0.95 ... 0 bar
Operating pressure	-13.775 ... 0 psi
Nominal operating pressure	-70 kPa
Nominal working pressure	-0.7 bar
Nominal operating pressure (psi)	-10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
PWIS conformity	VDMA24364 zone III
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Retention force at nominal operating pressure	72.6 N
Product weight	13.9 g
Color	blue
Shore hardness	60 +/- 5
Materials note	Conforms to RoHS
Material suction cup	PUR