


# Limit stop element YSRWJ-7-10-A

Part number: 192967  
Product to be discontinued

FESTO

[for linear module HMPL.](#)

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

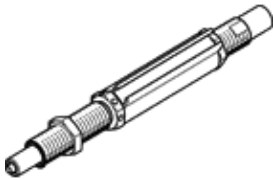

## Data sheet

Feature	Value
Size	7
Stroke	10 mm
Cushioning	self-adjusting Soft characteristic
Assembly position	Any
Precision adjustment	0.03 mm
Position detection	For proximity sensor
Max. impact speed	3 m/s
Reset time short	$\leq 0.2$ s
Reset time long	$< 1$ s
Mode of operation	single-acting pushing action
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	0 ... 60 °C
Cushioning length	10 mm
Max. stop force	300 N
Max. energy consumption per stroke	2 J
Max. energy consumption per hour	15,000 J
Max. residual energy	0.01 J
Reset force	1.7 N
Product weight	75 g
Mounting type	with lock nut
Material seals	NBR
Material housing	Brass Nickel plated
Material piston rod	High alloy steel