


Plug socket with cable KMYZ-4-24-0,5-B

Part number: 193690

FESTO

For high speed valves

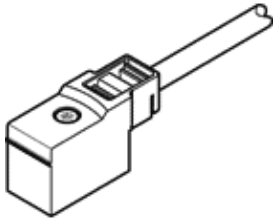

Data sheet

Feature	Value
Mounting type	On solenoid valve with M2 central screw
Assembly position	Any
Product weight	10 g
Electrical connection	Plug socket angled Cable Rectangular design, MSZC
Operating voltage range DC	3 ... 36 V
Nominal operating voltage DC	24 V
Acceptable current load at 40°C	1 A
Protective earth connection	Not available
Cable length	0.5 m
Cable attribute	Standard
Cable structure	2x0,35
Protection class	IP40
Ambient temperature	-10 ... 50 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PA
Material electrical contact	Bronze