 



Bellows cylinder EB-325-215

Part number: 193790

FESTO

Maintenance-free, no stick/slip effect.

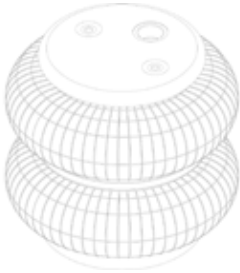

Data sheet

| Feature | Value |
|---|---|
| Size | 325 |
| Required installation diameter | 340 mm |
| Stroke | 215 mm |
| Max height when extended | 305 mm |
| Max. tipping angle | 20 deg |
| Max. offset | 20 mm |
| Min. installation height | 75 mm |
| Mode of operation | single-acting |
| Working pressure | 0 ... 8 bar |
| Operating medium | Compressed air to ISO 8573-1:2010 [-:~:4] |
| Note on operating and pilot medium | Lubricated operation not possible |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -40 ... 70 °C |
| Reset force | 300 N |
| Product weight | 4,800 g |
| Mounting type | with internal (female) thread |
| Pneumatic connection | G1/4 |
| Materials note | Conforms to RoHS |
| Material bellows | NR/BR |
| Material housing | Steel Galvanized |