


# Planar surface gantry EXCH-60-

Part number: 1939785

FESTO

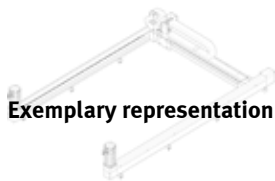

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	60
Assembly position	Vertical Horizontal
Design structure	Planar surface gantry
Working pressure	≤ 8 bar
Max. horizontal acceleration	50 m/s <sup>2</sup>
Max. vertical acceleration	30 m/s <sup>2</sup>
Max. horizontal speed	5 m/s
Max. vertical speed	3 m/s
Repetition accuracy	±0,1 mm
Duty cycle	100 %
CE symbol (see declaration of conformity)	according to EU machines guideline
UKCA marking (see declaration of conformity)	To UK instructions for machines
PWIS conformity	VDMA24364 zone III
Storage temperature	-10 ... 60 °C
Relative air humidity	0 - 90 % non-condensing
Sound pressure level	81 dB(A)
Protection class	IP40
Ambient temperature	10 ... 50 °C
Rated load with maximum dynamic response	6 kg
Mounting type	With mounting kit With adjusting kit With slot nuts
Materials note	Conforms to RoHS