


# Axial kit EAMM-A-D60-80P

Part number: 1977073

★ Core product range

Suitable for electric drives.

FESTO

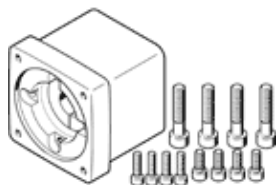

## Data sheet

| Feature                  | Value                |
|--------------------------|----------------------|
| Assembly position        | Any                  |
| PWIS conformity          | VDMA24364-B2-L       |
| Storage temperature      | -25 ... 60 °C        |
| Relative air humidity    | 0 - 95 %             |
| Protection class         | IP40                 |
| Ambient temperature      | -10 ... 60 °C        |
| Transferable torque      | 17 Nm                |
| Product weight           | 1,040 g              |
| Interface code, actuator | D60A<br>D60B<br>D60C |
| Interface code, motor in | 80P                  |
| Materials note           | Conforms to RoHS     |