


Clamping sleeve EAMH-86-16-C27.3

Part number: 2430397

FESTO

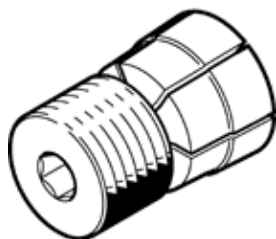

Data sheet

Feature	Value
Size	86
Assembly position	Any
Max. speed	5,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-10 ... 60 °C
Mass moment of inertia	9.5 kgmm ²
Product weight	94 g
Materials note	Conforms to RoHS