


# Subbase

## VABP-S1-1V1G-G14-2M-R3

Part number: 2614863

FESTO

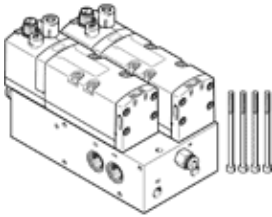

### Data sheet

Feature	Value
Width	42 mm
Function port 32	G1/8
Function port 34	G1/8
Pneumatic port 22	Subbase G1/4
Pneumatic port 44	Subbase G1/4
Assembly position	Any
Working pressure	0 ... 16 bar
Pilot pressure	3 ... 8 bar
Standard nominal flow rate	1,400 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [6:4:4]
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	0 ... 50 °C
Ambient temperature	0 ... 50 °C
Product weight	2,480 g
Pilot air port 14	G1/8
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 4	G1/4
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminum alloy
Material o-ring	NBR
Material screws	Steel