


# Axial kit EAMM-A-D50-87A

Part number: 2733781

★ Core product range

Suitable for electric drives.

FESTO

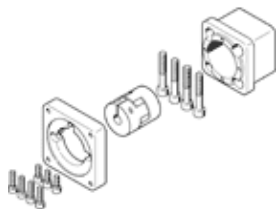

## Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	12 Nm
Product weight	860 g
Interface code, actuator	D50B
Interface code, motor in	87A
Materials note	Conforms to RoHS