

 

Bellows cylinder

EB-80-20

Part number: 2748903

FESTO

Maintenance-free, no stick/slip effect.

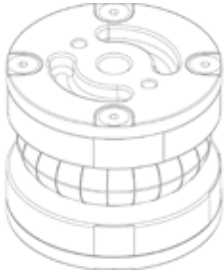

Data sheet

Feature	Value
Size	80
Required installation diameter	95 mm
Stroke	20 mm
Max height when extended	70 mm
Max. tipping angle	10 deg
Max. offset	5 mm
Min. installation height	50 mm
Mode of operation	single-acting
Working pressure	0 ... 8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [-:~:4]
Note on operating and pilot medium	Lubricated operation not possible
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 70 °C
Reset force	400 N
Product weight	500 g
Mounting type	with internal (female) thread
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material bellows	CR
Material housing	Aluminum casting