


Connector block MRS-2

Part number: 2844247

FESTO

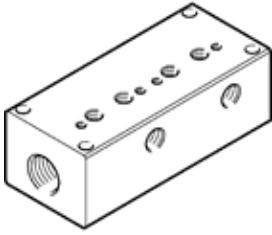

Data sheet

Feature	Value
Size	2
Max. number of valve positions	2
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	2.5 Nm
Max. tightening torque, wall mounting	4 Nm
Product weight	365 g
Pneumatic connection, port 1	G3/8
Materials note	Conforms to RoHS
Material of connecting plate	Wrought Aluminum alloy