


Plug socket with cable KMF-1-24DC-2.5-LED

Part number: 30935

★ Core product range

Pre-assembled, for F solenoids.

FESTO

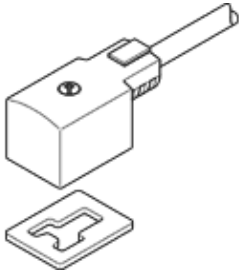

Data sheet

Feature	Value
Switching position indicator	LED
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	170 g
Electrical connection	Plug socket
Nominal operating voltage DC	24 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	6 mm
Cable structure	3x0,75
Protection class	IP67 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Material cable sheath	PVC
Material housing	PC POM
Material electrical contact	Bronze