


# Plug socket with cable KMV-1-230AC-5

Part number: 30942

FESTO

Pre-assembled, for V solenoids.

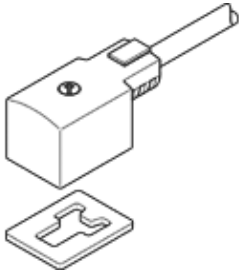

## Data sheet

Feature	Value
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	320 g
Electrical connection	Plug socket Plug pattern type B to EN 175301-803
Nominal operating voltage, AC	230 V
Polarity protected	for all electrical connections
Protective earth connection	Available
Cable length	5 m
Cable diameter	6 mm
Cable structure	3x0,75
Protection class	IP67 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PC
Material electrical contact	Bronze