


# Plug socket with cable

## KME-1-24-2.5-LED

Part number: 30943

FESTO

Pre-assembled, for ME valves.

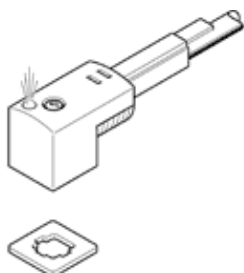

### Data sheet

Feature	Value
Signal status display	Yellow LED
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	135 g
Electrical connection 1	Angled socket, square design, 3-pin, type C
Electrical connection 2	Open end, 2-wire
Nominal operating voltage DC	24 V
Acceptable current load at 40°C	4 A
Protective earth connection	Not available
Cable length	2.5 m
Cable attribute	For static applications
Min. cable bending radius	52 mm
Cable diameter	5.2 mm
Cable diameter tolerance	± 0,1 mm
Cable structure	2x0,75
Protection class	IP67 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	TPE-U(PU)
Material seals	NBR
Material electrical contact	Silver-plated copper alloy