


Front unit ERMH-11-E17-30

Part number: 3385153
Product to be discontinued

FESTO

Type to be discontinued. Available until 2022. See Support Portal for alternative products.

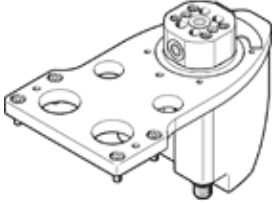

Data sheet

| Feature | Value |
|--|----------------------------------|
| Size | 11 |
| Design structure | Electro-mechanical rotary module |
| Assembly position | Any |
| Rotation angle | Endless |
| Gear unit ratio | 30:1 |
| Nominal torque | 1.8 Nm |
| Repetition accuracy | ±0,01 ° |
| Max. axial force | 300 N |
| Product weight | 1,298 g |
| Duty cycle | 100 % |
| Nominal motor current | 0.74 A |
| Motor type | Servomotor |
| Max. output speed | 200 1/min |
| Nominal operating voltage, AC | 230 V |
| Nominal motor power | 22.1 W |
| Peak current | 1.5 A |
| Max. pull-out torque static | 40 Nm |
| Peak torque | 4.5 Nm |
| Permissible mass moment of inertia of load | 0.006 kgm ² |
| Protection class | IP40 |
| Ambient temperature | 0 ... 40 °C |
| Materials note | Conforms to RoHS |