


# Intermediate plate MUHX2-ZP-D-3-24G

Part number: 34935  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

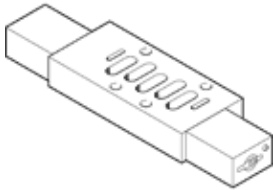

## Data sheet

| Feature                                   | Value   |
|---|---|
| Nominal size                              | 14.5 mm   |
| Grid dimension                            | 72 mm   |
| Type of actuation                         | electrical  |
| Assembly position                         | Any   |
| Manual override                           | Pushing   |
| Type of reset                             | mechanical spring   |
| Type of piloting                          | direct  |
| Flow direction                            | non reversible  |
| Working pressure                          | -0.9 ... 10 bar   |
| Pilot pressure                            | 2 ... 10 bar  |
| Nominal operating voltage DC              | 24 V  |
| Permissible voltage fluctuation           | +/- 10 %  |
| Authorization                             | c UL us - Recognized (OL)   |
| CE symbol (see declaration of conformity) | according to EU-EMV guideline   |
| Operating medium                          | Compressed air in accordance with ISO8573-1:2010 [7:4:4]                    |
| Note on operating and pilot medium        | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC   | 2 - Moderate corrosion stress   |
| PWIS conformity                           | VDMA24364-B2-L  |
| Storage temperature                       | -20 ... 40 °C   |
| Medium temperature                        | -5 ... 50 °C  |
| Protection class                          | IP65  |
| Pilot medium                              | Compressed air in accordance with ISO8573-1:2010 [7:4:4]                    |
| Ambient temperature                       | -5 ... 50 °C  |
| Product weight                            | 500 g   |
| Mounting type                             | with through hole   |
| Materials note                            | Conforms to RoHS  |
| Material seals                            | NBR   |