


# Coupling plug KS2-CK-4

Part number: 4090

FESTO

For self-closing quick coupling connectors.

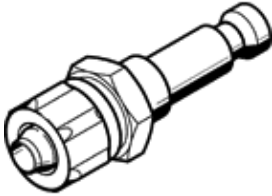

## Data sheet

Feature	Value
Nominal size	2.7 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	123 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	11 g
Pneumatic connection, port 1	CK-4
Materials note	Conforms to RoHS