
 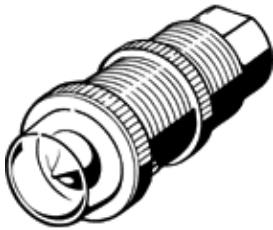


Pressure indicator OH-22-GN

Part number: 4237

FESTO



Data sheet

| Feature | Value |
|------------------------------------|---|
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 ... 45 °C |
| Product weight | 25 g |
| Pneumatic connection | G1/8 |
| Materials note | Conforms to RoHS |