


One-way flow control valve GRF-PK-3X2

Part number: 4566

FESTO

With 2n subbase and barbed fitting for 3mm tubing ID.

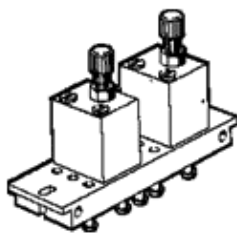

Data sheet

Feature	Value
Valve function	One-way flow control function
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Adjusting element	Knurled screw
Mounting type	with through hole
Standard nominal flow rate in flow control direction	45 l/min
Standard nominal flow rate in non-return direction	45 l/min
Working pressure	0.5 ... 8 bar
Ambient temperature	-10 ... 60 °C
Material housing	Wrought Aluminum alloy
Assembly position	Any
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Product weight	145 g
Material adjusting screw	Brass