


Clevis foot mounting LN-80

Part number: 5151

FESTO

For swivel mounting of cylinders DNC, DNGU, DNGUT, DNG, DNU, AEVU, ADVU, ADVUP, ADVUP.

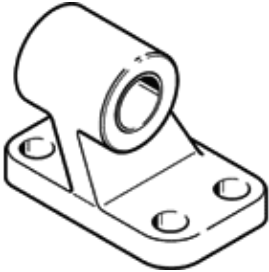

Data sheet

Feature	Value
Size	80
Based on the standard	ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 150 °C
Product weight	877 g
Materials note	Conforms to RoHS
Material mounting	Nodular graphite cast iron