


# Plug SD-SUB-D-ST25

Part number: 527522

FESTO

25-pin, for connection to multi-pin plug distributor MPV-E-E/A-M-12 or CPX-AB-M12-M8-KL.

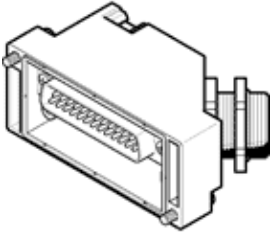

## Data sheet

Feature	Value
Mounting type	with through hole
Assembly position	Any
Product weight	51 g
Electrical connection	25-pin Plug Sub-D
Operating voltage range DC	$\leq 250$ V
Operating voltage range AC	$\leq 250$ V
Permissible current load	5 A
Cable gland connection	Pg11
Permissible cable diameter	7 ... 12 mm
Protection class	IP65
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA
Material seals	NBR
Material electrical contact	Copper alloy Gold plated