


Subbase VABS-B6-PB-Q

Part number: 537519

FESTO

For external, auxiliary pilot air.

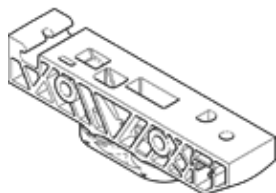

Data sheet

Feature	Value
Grid dimension	21 mm
Corrosion resistance classification CRC	2
Max. tightening torque, valve mounting	2 Nm
Max. tightening torque, wall mounting	3 Nm
Product weight	22 g
Pilot air port 12	M5
Pilot air port 14	M5
Pneumatic connection, port 1	For 18 mm cartridge
Pneumatic connection, port 3	G1/4
Materials note	Free of copper and PTFE Conforms to RoHS
Materials information for subbase	PA-reinforced