


Electronics module

VMPA2-FB-EMS-4

Part number: 537983

FESTO

For valve manifold MPA-S with fieldbus connection for 4 solenoid coils, not electrically isolated.

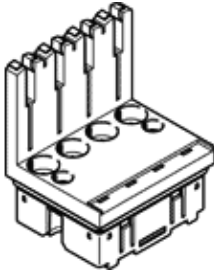

Data sheet

| Feature | Value |
|--|--|
| Diagnosis | Undervoltage, valves |
| Max. number of valve positions | 2 |
| Max. number of solenoid coils | 4 |
| Intrinsic current consumption at load voltage | 3 mA |
| Intrinsic current consumption at operating voltage | 8 mA |
| Nominal breakaway current per solenoid coil | 99 mA up to 24 ms |
| Nominal current with current reduction | 18 mA after 24 ms |
| Corrosion resistance classification CRC | 1 - Low corrosion stress (when installed) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Product weight | 20 g |
| Material housing | POM |
| Materials note | Conforms to RoHS |