


# Connecting cable NEBV-S1G25-K-2.5-N-LE25

Part number: 538225

FESTO

For multi-pin plug connection to valve manifold VTUB, with Sub-D plug, 25-pin.

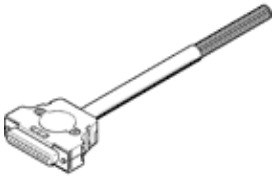

## Data sheet

Feature	Value
Mounting type	4-40 UNC-2B
Product weight	490 g
Electrical connection 1	Socket sub-D, 25-pin
Electrical connection 2	Open end, 25-wire
Nominal operating voltage DC	24 V
Cable length	2.5 m
Cable attribute	Standard
Min. cable bending radius	105 mm
Cable diameter	10.5 mm
Cable structure	20x0,25+5x0,34
Protection class	IP65 IP67 in assembled condition
Ambient temperature with flexible cable installation	-5 ... 50 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	PVC
Material housing	PBT
Material of union nut	PA
Material seals	TPE-O