


Condensate drain PWEA-AP-3D

Part number: 538678

FESTO

For external attachment, with independent electrical controller.

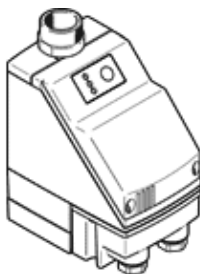

Data sheet

| Feature | Value |
|--|--|
| Type of actuation | electrical |
| Assembly position | Vertical +/- 5° |
| Manual override | Pushing |
| Condensate drain | fully automatic |
| Design structure | External, electrical, fully automated |
| Measured variable | Fill-level |
| Valve function | closed 3/2 monostable |
| Control elements | Membrane keypad With test key |
| Ready status display | LED |
| Operating status display | LED |
| Working pressure | 0.8 ... 16 bar |
| Alarm output | Contact-type |
| Nominal operating voltage DC | 24 V |
| Nominal capacity, condensate drain | 2 W |
| Operating medium | Compressed air |
| Corrosion resistance classification CRC | 2 |
| Storage temperature | -10 ... 60 °C |
| Medium temperature | 1 ... 60 °C |
| Protection class | IP65 to IEC 60529 |
| Safety class | III |
| Ambient temperature | 1 ... 60 °C |
| Product weight | 700 g |
| Electrical connection | Plug M12x1 5-pin Round design |
| Mounting type | Line installation |
| Condensate drain connection | PK-8 |
| Pneumatic connection | G1/2 |
| Material information, condensate container | Wrought Aluminum alloy |
| Materials note | Free of copper and PTFE |
| Materials information, housing | Plastic |