


# Multi-pin CPV10-VI-P6-M7-C

Part number: 538809  
Classic - do not use for new projects

FESTO

[For valve manifold CPV.](#)

Modern alternatives can be found by entering the first four characters of the type code in the search field.

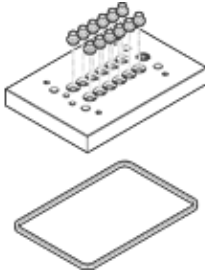

## Data sheet

| Feature   | Value  |
|---|--|
| CE symbol (see declaration of conformity)         | according to EU-Ex protection guideline (ATEX)   |
| UKCA marking (see declaration of conformity)      | To UK EX instructions<br>To UK RoHS instructions   |
| Explosion protection certification outside the EU | EPL Db (GB)<br>EPL Db (IEC-EX)<br>EPL Dc (IEC-EX)<br>EPL Gb (GB)<br>EPL Gb (IEC-EX)<br>EPL Gc (IEC-EX) |
| Certificate issuing department                    | IECEX TUR 12.0002X<br>TÜV 06 ATEX 7334 X<br>TÜV 21 UKEX 7013 X   |
| ATEX category Gas                                 | II 2G  |
| ATEX category Dust                                | II 2D  |
| Explosion ignition protection type Gas            | Ex eb IIC Gb   |
| Explosion ignition protection type Dust           | Ex tb IIIC Db  |
| Explosion-proof ambient temperature               | -10°C ≤ Ta ≤ +60°C   |
| Corrosion resistance classification CRC           | 2 - Moderate corrosion stress  |
| PWIS conformity                                   | VDMA24364-B1/B2-L  |
| Product weight                                    | 390 g  |
| Materials note                                    | Conforms to RoHS<br>Halogen-free<br>Free of copper   |
| Material seals                                    | NBR  |
| Material plate                                    | Wrought Aluminum alloy   |