


Socket connector MSSD-C-M16

Part number: 539709

FESTO

For solenoid coils and valves, port pattern per DIN EN 175 301, type A.

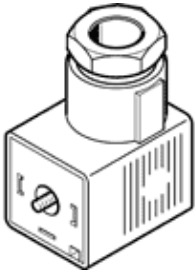

Data sheet

Feature	Value
Connection frequency	50
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	38 g
Electrical connection	3-pin Plug socket angled Plug pattern type A to EN 175301-803 Per DIN EN 175301-803 Cubic design
Cable gland connection	M16
Permissible cable diameter	6 ... 8 mm
Terminal cross-section	1.5 mm ²
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 115 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA-reinforced
Material seals	HNBR