


Ball valve actuator unit VZPR-BPD-22-R34

Part number: 540513

FESTO

Brass, with double-acting drive DAPS 2/2-way, nominal width 3/4",
PN40, thread EN 10226-1.

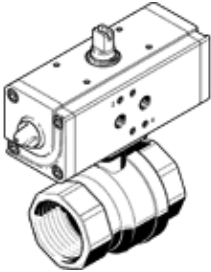

Data sheet

| Feature | Value |
|---|--|
| Design structure | 2-way ball valve Swivel actuator |
| Type of actuation | electrical pneumatic |
| Assembly position | Any |
| Mounting type | CNOMO with internal (female) thread |
| Process valve connection | Rp3/4 |
| Switching position indicator | Knob direction = Flow direction |
| Nominal diameter DN | 20 |
| Working pressure, ball valve actuator | 1 ... 8.4 bar |
| Nominal pressure of process valve | 40 |
| Medium temperature | -20 ... 150 °C |
| Ambient temperature | -20 ... 80 °C |
| PWIS conformity | VDMA24364 zone III |
| Product weight | 1,500 g |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |