


Power supply unit SVG-1/230VAC-48VDC-10A

Part number: 542404
Product to be discontinued

FESTO

With 48 V DC rated output voltage and 10 A rated output current.
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

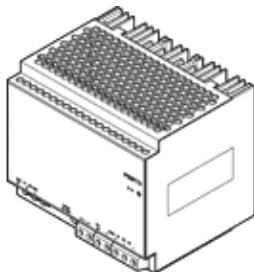

Data sheet

Feature	Value
Width	125 mm
Height	130 mm
Length	157 mm
Assembly position	Free convection
Primary supply	Single-phase
Input current	5,1 - 2,3 A
Nominal output voltage DC	48 V
Nominal output current	10 A
Input voltage range AC	100 ... 240 V
Power failure buffering	50 ms
Line frequency	45 ... 65 Hz
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
Storage temperature	-40 ... 85 °C
Relative air humidity	95%
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Authorization	C-Tick c UL us - Listed (OL)
Product weight	2,800 g
Mounting type	with top-hat rail
Materials note	Contains PWIS substances