


# Parallel kit EAMM-U-D32-40A

Part number: 543150

FESTO

Suitable for electric drives.

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

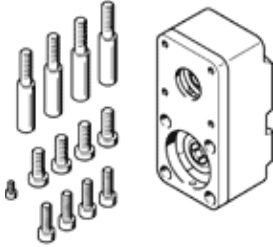

## Data sheet

Feature	Value
Size	32
Assembly position	Any
Max. speed	6,000 1/min
PWIS conformity	VDMA24364 zone III
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	2.931 kgmm <sup>2</sup>
No-load driving torque	0.05 Nm
Transferable torque	1 Nm
Product weight	300 g