


# Parallel kit EAMM-U-D60-52C

Part number: 543168

FESTO

Suitable for electric drives.

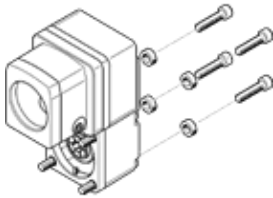

## Data sheet

| Feature                | Value                    |
|------------------------|--------------------------|
| Size                   | 63                       |
| Assembly position      | Any                      |
| Max. speed             | 4,000 1/min              |
| Storage temperature    | -25 ... 60 °C            |
| Relative air humidity  | 0 - 95 %                 |
| Protection class       | IP40                     |
| Ambient temperature    | 0 ... 50 °C              |
| Mass moment of inertia | 70.5 kgmm <sup>2</sup>   |
| No-load driving torque | 0.3 Nm                   |
| Transferable torque    | 5.5 Nm                   |
| Product weight         | 1,630 g                  |
| Materials note         | Contains PWIS substances |