


Parallel kit EAMM-U-E24-32B

Part number: 543225
Product to be discontinued

FESTO

[Suitable for electric drives.](#)

[Type to be discontinued. Available until 2019. See Support Portal for alternative products.](#)

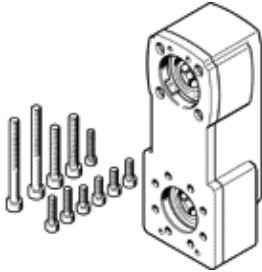

Data sheet

Feature	Value
Size	18
Assembly position	Any
Max. speed	3,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	3.016 kgmm ²
No-load driving torque	0.05 Nm
Transferable torque	1 Nm
Product weight	240 g
Materials note	Contains PWIS substances