


Electronics module VMPA2-FB-EMS-D2-4

Part number: 543332

FESTO

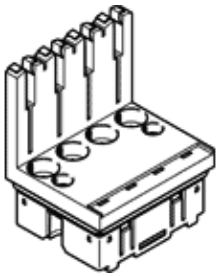

Data sheet

Feature	Value
Diagnosis	Condition Monitoring Wire break per valve coil Short circuit of valves Undervoltage, valves
Max. number of valve positions	2
Max. number of solenoid coils	4
Intrinsic current consumption at load voltage	3 mA
Intrinsic current consumption at operating voltage	8 mA
Nominal breakaway current per solenoid coil	99 mA up to 24 ms
Nominal current with current reduction	18 mA after 24 ms
Corrosion resistance classification CRC	1 - Low corrosion stress (when installed)
PWIS conformity	VDMA24364-B1/B2-L
Product weight	20 g
Material housing	POM
Materials note	Conforms to RoHS