


Subbase VMPA2-IC-AP-1-EX2

Part number: 545449

FESTO

For valve terminal MPA-S.

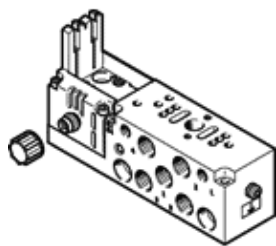

Data sheet

Feature	Value
Width	30.5 mm
Length	107.3 mm
Grid dimension	21 mm
Working pressure	3 ... 8 bar
Pilot pressure	3 ... 8 bar
ATEX category Gas	II 3G
Explosion ignition protection type Gas	Ex nA II T4 X
ATEX category Dust	II 3D
Explosion ignition protection type Dust	Ex tD A22 IP54 T95°C X
Explosion-proof ambient temperature	-5°C ≤ Ta ≤ +50°C
Corrosion resistance classification CRC	0
Ambient temperature	-5 ... 50 °C
Electrical connection	Plug M8
Mounting method for subbase	with through hole
Pilot exhaust port 82/84	M5
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 4	G1/8
Pneumatic connection, port 5	G1/8
Materials note	Conforms to RoHS
Materials information for subbase	Aluminum die cast